


Data Sheet

20.04.2026

Fiber Optic Breakout Cable VB01-0486

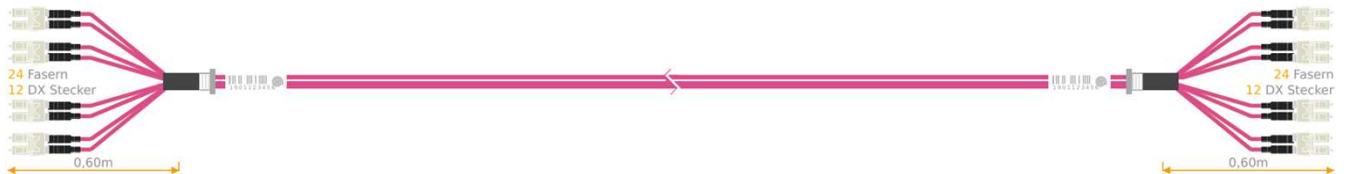

Connector Side A



Cable cross-section scheme



Connector Side B

CONNECTOR SIDE A		CONNECTOR SIDE B
LC/UPC Multimode DX	CONNECTOR DESCRIPTION	LC/UPC Multimode DX
IEC 61754-20, JIS C 5964-20	DESIGN SPECIFICATION	IEC 61754-20, JIS C 5964-20
Seikoh Giken	MANUFACTURER	Seikoh Giken
Ø1.25mm, ceramics, axial suspended	FERRULE	Ø1.25mm, ceramics, axial suspended
-40°C to +75°C	OPERATION TEMPERATURE	-40°C to +75°C
Plastic / Beige	MATERIAL OF FERRULE	Plastic / Beige
500	PLUG CYCLES	500
≤ 0.20dB	TYPICAL INSERTION LOSS (IL)	≤ 0.20dB
Black	BEND PROTECTION	Black
0.60m	WHIP	0.60m

CABLE			
CABLE TYPE	I-V(ZN)HH	MANUFACTURER	WEINERT
NUMBER OF FIBERS	24	FIBER CLASS	OM4 BI
OUTER DIAMETER	14.2mm	CABLE COLOR	Heather Violet
CLOAK MATERIAL	FRNC	PULL STRENGTH	1000N
CABLE WEIGHT	200kg/km	OPERATION TEMPERATURE	-25°C to +70°C