


Adhesive Mounting Bases

Cable Tie Mounting Bases - Acrylic Adhesive

HellermannTyton Adhesive Cable Tie Mounting Bases are used with T18 through T150 Series cable ties to provide stability when securing bundles. The mounts are installed using the adhesive backing and/or by securing two or four screws. The 4-way opening allows the cable ties to be inserted parallel or perpendicular to the wire bundles. Acrylic-based adhesive allows for a permanent bond to a wide range of wood, metal and plastic surfaces.

Features and Benefits

- Acrylic adhesive offers excellent chemical, water and salt resistance and is unaffected by vibration.
- 4-way opening allows cable ties to be installed parallel or perpendicular to bundles.
- Predrilled holes extend mounting options and security.
- Extended adhesive liner is easy to remove quickly.

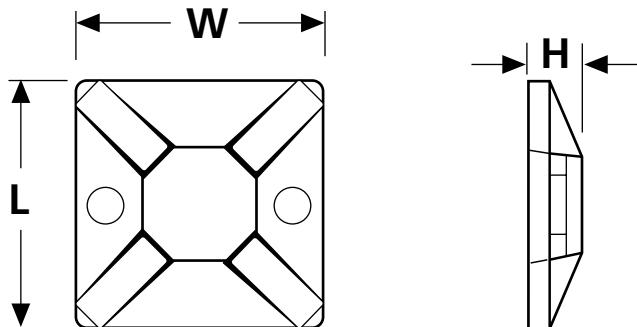

PART NO.	TYPE	Cable Tie Series	Length (L) in. (mm)	Width (W) in. (mm)	Height (H) in. (mm)	Material	Color	Pkg. Qty.
MB3A0A2H4	MB3A	T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.8)	PA66	Black	500
MB3A10A2H4		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.8)	PA66	White	500
MB3A10A2C2		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.8)	PA66	White	100
MB4A0A2H4	MB4A	T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.8)	PA66	Black	500
MB4A10A2C2		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.8)	PA66	White	100
MB4A10A2H4		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.8)	PA66	White	500
151-00810		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.8)	PA66UV	Black	100
151-00646		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.8)	PA66UV	Black	500
MB5A0A2F4	MB5A	T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	Black	250
MB5A10A2F4		T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	White	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

*This product meets UL standards. Please see appendix for specific file numbers.

Bundling and Securing

Cable Tie Mounts


Adhesive Mounting Bases

Cable Tie Mounting Bases - Acrylic Foam Adhesive

Adhesive Fastened Mounting Bases are used with 18 through 150 lb. cable ties to provide stability when securing bundles. The mounts are installed using the adhesive backing and/or by securing two or four screws. The four-way opening allows the cable ties to be inserted parallel or perpendicular to the wire bundles.

Features and Benefits

- Screwable or self-adhesive versions.
- Simple to install with a screw or bolt.
- Excellent security, particularly in areas of high vibration.
- Maximum surface area with adhesive to achieve high pull-off force.
- 4-way entry for cable tie for quicker and more flexible installation.

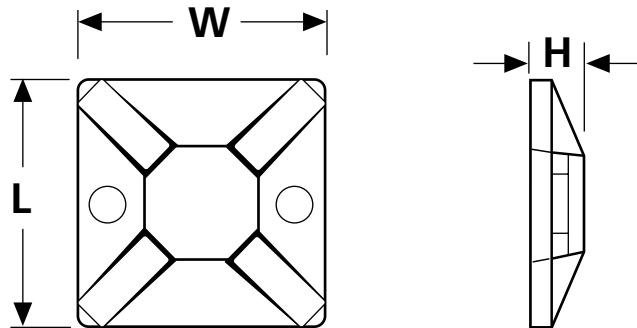

PART NO.	TYPE	Cable Tie Series	Length (L) in. (mm)	Width (W) in. (mm)	Height (H) in. (mm)	Material	Color	Pkg. Qty.
151-01630	MB3A	T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.8)	PA66HIRHSUV	Black	500
151-01629		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.8)	PA66HIRHSUV	Black	100
151-01632	MB4A	T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66HIRHSUV	Black	500
151-01631		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66HIRHSUV	Black	100
151-01634	MB5A	T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66HIRHSUV	Black	250
151-01633		T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66HIRHSUV	Black	100

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.