



Identification Products



Identification Products

Table of Contents

TagPrint® Pro 4.0 Software	4
Printers	6
Thermal Transfer Labels	10
Self-Laminating Labels	12
Paint Mask Labels	14
Foam Nameplates	15
ShrinkTrak Labels	16
TipTags	18
Pre-Printed Header Labels	19
Continuous Rolls	20
Specifications	22

TagPrint**PRO** 4.0

Streamline Productivity and Reduce Operator Errors with the Complete Label Management Solution from HellermannTyton

Get more done in a fraction of the time with HellermannTyton's feature-rich labeling design software, TagPrint® Pro 4.0. There's nothing more powerful, especially when paired with our high-quality thermal transfer, laser and inkjet printable labels, and our complete line of desktop thermal transfer printers.

From Full Custom to Hands-Off Label Creation

TagPrint Pro 4.0 puts a powerful yet easy-to-use interface at your fingertips. Get going fast with pre-saved designs of the most common safety and solar labels. Or, build your label from a template or from scratch using intuitive design tools that manipulate bar codes, text and graphics with ease.

Store your label designs and find them again quickly with the help of live design preview. Need to move faster? TagPrint Pro's impressive, built-in print automation capabilities will run entire batches of labels with one wave of a bar code scanner.

Produce professional labels on the shop floor or at a remote jobsite. TagPrint Pro 4.0 allows you the freedom to identify cables, tubes, components, panels and more – and do so efficiently.

Compatible with Windows® 7, 8.1 and 10, TagPrint Pro 4.0 operates seamlessly in most production environments.

Familiar Windows-based Navigation

TagPrint® Pro 4.0's interface offers quick and easy access to the controls. Tabs are organized by activity, such as "Label," "Table" and "Print."

At-a-glance Interface

User can view object properties, data and actual label layout at the same time.

Pre-saved Designs

Software comes preloaded with commonly used, code-compliant safety and solar label designs and icons.

Expanded Import Capabilities and "Live Sync"

TagPrint Pro has a wide range of data import capabilities, including XMT, CSV and ODBC, which will refresh automatically, or in the case of Excel, just open directly in the program.

Built-in Security

Lockout or password protect label designs and data tables from unauthorized label editing.

Visual File Preview

When searching through label designs in the File | Open window, you can see each file displayed as it actually looks when printed as opposed to seeing just the file name.

"Pin" Favorites

Create shortcuts to frequently used label designs and data tables, making them immediately available in the file menu.

Single-user License or Network Version Available

TagPrint Pro 4.0 is available for single users or network installations to share printers, label designs and data tables from multiple workstations at one location.

Game-Changing Print Automation

Print automation unleashes your productivity, saving you time and virtually eliminating costly operator errors.

- Save frequently used labels individually or as a group under a single file name or job number.
- No need to search for and open files individually – simply enter the job number or scan a bar code on the work order for instant printing.
- Batch print to one or more printers at the same time – no waiting for one file to print before the next one begins.
- Store all print quantities, multiple printer destinations, data instructions and more within the file – no need for the operator to enter any information and make potential mistakes.
- Add optional user prompts to customize quantities, control numbers and more.



Identification

Printers

CIJ4800 Series Inkjet Printer

The HellermannTyton CIJ4800 is a full-color, high-resolution printer for creating photo-quality labels and signs in a single pass. It minimizes material waste as well as needed supplies. The high-yield inkjet cartridge contains high-performance pigment-based inks for maximum resistance to chemicals and solvents. Applications include general or industrial-grade safety signage, GHS, lean/5S and visual workplace identification. The system is easy to use and works with HellermannTyton TagPrint® Pro labeling software.



CIJ4800 Printer, 593-11000

Features and Benefits

- No need to change label stock or ribbon colors for each "Warning" type, saving time and reducing inventory.
- Unlimited label designs and colors, reducing the need to order custom labels online.
- Print icons, images or even full-color photos at 4800 dpi, for professional-looking labels every time.
- Print permanent or temporary arc-flash markings as needed for machine and electrical installations to meet NEC and NFPA requirements.
- TagPrint Pro 4.0 contains pre-made safety sign templates and images, including GHS signage and pictograms, making label selection easy and fast while ensuring complete ANSI and OSHA code compliance.



See page 27 for available label stock.

TT230SMC Series Thermal Transfer Printers

HellermannTyton's TT230SM Series thermal transfer printers deliver high speed and precision not found in many other small desktop printers.

Features and Benefits

- Designed for low- to medium-volume printing of thermal transfer labels and ShrinkTrak.
- LCD user interface for easier setup, diagnostics and adjustments.
- 300 dpi print head for high-resolution printing.
- Label holder included for convenient loading of any size media.
- Small footprint for easy transport to jobsites or around the shop.
- Ethernet ready for wireless network connectivity.
- Print speeds up to 3 in (76.2mm) per second for fast label production.
- 2 MB flash/8 MB DRAM for accepting large label files that require a lot of data.



TT230SM Standard printer, 556-00230



TT230SMC Printer with cutter, 556-00240



On-screen help menus

Identification

Printers

TTM430 / TTM460 Series Thermal Transfer Printers


HellermannTyton's TTM430 and TTM460 Series thermal transfer printers feature a streamlined touch screen and rapid printing.

Features and Benefits


- Designed for medium- to high-volume printing of thermal transfer labels and ShrinkTrak.
- Touch LCD with visual prompts for easier operation.
- 300 dpi (TTM430) and 600 dpi (TTM460) print head for high- to ultra-high-resolution printing.
- Ethernet ready for wireless network connectivity.
- Print speeds up to 7.87" (200 mm) per second for fast label production.
- Adjustable gap sensor detects a wide variety of label types.
- Print head automatically adjusts to varying media thickness.
- Optional cutter faceplate for automatic cutting and kitting of printed labels.



*TTM430 Standard printer, 556-00430
TTM430SC Printer with cutter, 556-00443
TTM460 Printer with 600 dpi print head, 556-00460*

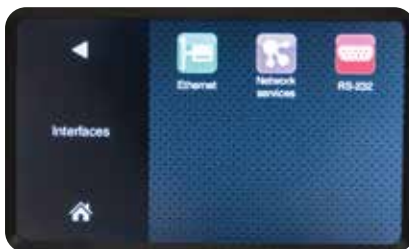

On-screen help menus

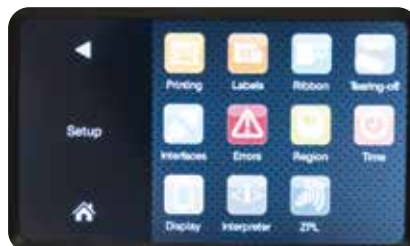

TT4030 Series Thermal Transfer Printers

HellermannTyton's TT4030 Series thermal transfer printers feature an informative display for simple navigation and instructional videos. The built-in caddy allows even the largest label rolls to fit inside.

Features and Benefits

- Premium-quality printer is designed for medium- to heavy-duty industrial applications.
- Ultra-fast print speeds up to 11.8 in (300 mm) per second.
- 300 dpi print head cleanly renders best-in-class high-definition graphics and text on labels, thermo plastics such as heat shrink and TipTags.
- Standard adjustments are made with the on-board tool, minimizing operator downtime.
- Optional premium quality accessories such as a perforator and cutter extend the printer's productivity.



TT4030 Premium printer, 556-04037



On-screen help menus



Identification

Thermal Transfer Labels

INDUSTRIAL CONTROL PANEL

HellermannTyton

Serial Number:	RC2356YUP77
Current:	125 Amperes
Largest Motor H.P.	20 Horsepower
Max OCP Device:	60 Amperes
Voltage:	460 - 480 Volts
Phase and Frequency:	3ph, 60 Hz
Short Circuit Current Rating:	100,000 Amperes RMS
Diagram Number:	HT-4322
NEMA Rating:	TYPE 2

TAG80T1-795

2 DISCONNECTS REQUIRED TO DE-ENERGIZE

TAG80T1-795 | 3.0" x 5.0"



UID MILITARY APPROVED LABEL MATERIAL - 7871

MIL-STD-810
ASTM D3330
ASTM D4060
UL Recognized
British Standard BS-5609

Unique Item Identifier (UID) military compliant labeling system. Tested by the Naval Surface Warfare Center (NSWC) for high and low temperature cycling, salt, fog, chemical and abrasion resistance and adhesive performance.

HellermannTyton

TAG33T1-DTH | 3.0" x 2.0"

(123) 456-7890

TAGPP3T4-822
.688" x .25"

TAG75T1-822

DATACOM WIRING INSIDE

TAG75T1-822
2.0" x .625"

PATCH

PANEL

WALL

PLATE

CLEAR

TAGPP1T6-822C

TAGPP1T6-822C
.625" x .33"

TERMINAL MARKING
BLOCK

01

02

03

04

05

06

07

08

09


10

TAG83T1-822

TAG83T1-822 | 4.0" x .312"

Identification

Thermal Transfer Labels

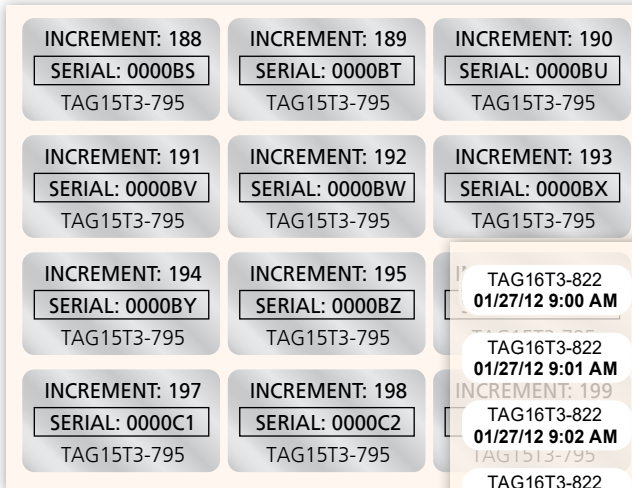

TAG15T3-795 | 1.0" x .5"



TAG82T2-822 | 1.5" x .25"

A2 A3 A4

TAG70T12-822 | .25" x .25"



TAG71T5-822
.5" x .43"



TAG28T4-250 | .8" X 1.43"



TAG16T3-822 | .9" x .25"



TAG69T1-336 | 2.0" x .275"



TAG76T1-795 | 2.5" x 2.0"



TAG73T1-795 | 2.0" x 1.0"

Identification

Self-Laminating Labels

TAG6T1-100B

Self-laminating for cables

Flat ribbon cables

Fiber optic cables

TAG6T1-100B | 2.0" x 3.75"

TAG24T1-100B

WIRE & CABLE MARKING

TAG24T1-100B
2.0" x 1.43"

TAG7T1-100B



**LARGE CABLES OR
CABLE BUNDLES**

Input: 120VAC 60 Hz 15W



**TAG
9T3-100B**

TAG9T3-100B
1.0" x 2.25"

General Copper
or Fiber Marker
TAG53T2-100B

TAG53T2-100B
1.5" x 1.437"

Sequentially Numbered

0021

TAG22T3-100B

TAG22T3-100B
1.0" x 1.43"

TAG7T1-100B | 2.0" x 7.37"



Identification

Self-Laminating Labels

**TAG
38T4
100B**



DANGER

HIGH VOLTAGE CABLE



CABLE GiC/81D
CABLE GiC/81D
CABLE GiC/81D
CABLE GiC/81D

DATA LINE



TAG9T3-100B

TAG1T1-100B
1.9" X 3.12"

TAG51T3-100B

TAG51T3-100B
1.0" x .75"

TAG10T2-100B | 2.0" x 2.25"

**TAG2T5
-100B**

**TAG26T6
-100B**

TAG26T6-100B
.5" x .75"

TAG9T3-100B
1.0" x 2.25"




TAG38T4-100B
1.0" x 7.37"

TAG2T5-100B
0.5" x 1.43"


Identification

Paint Mask Labels

Two-Piece Design

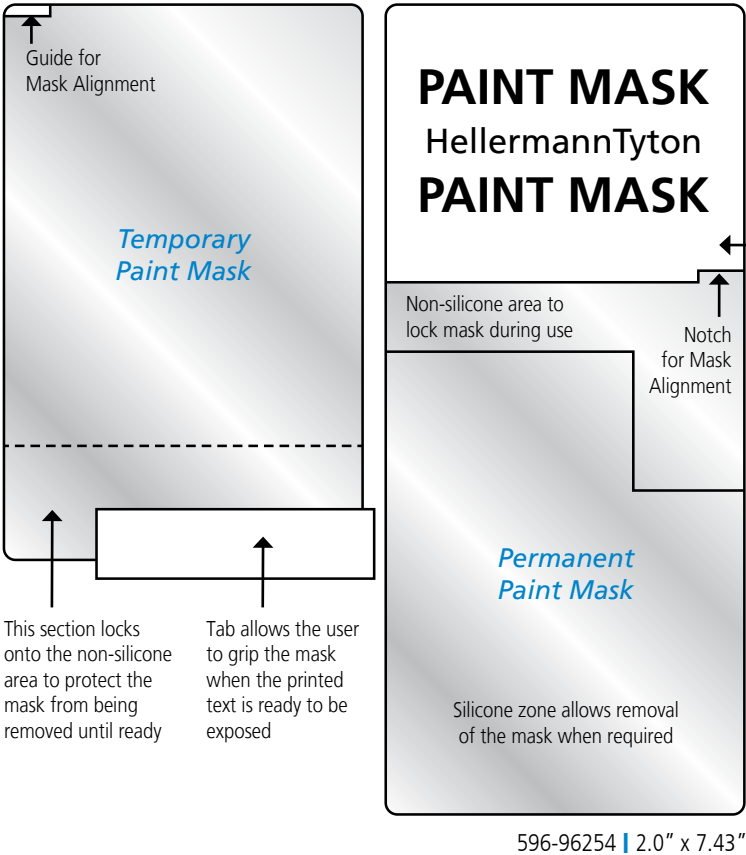

One-Piece Design

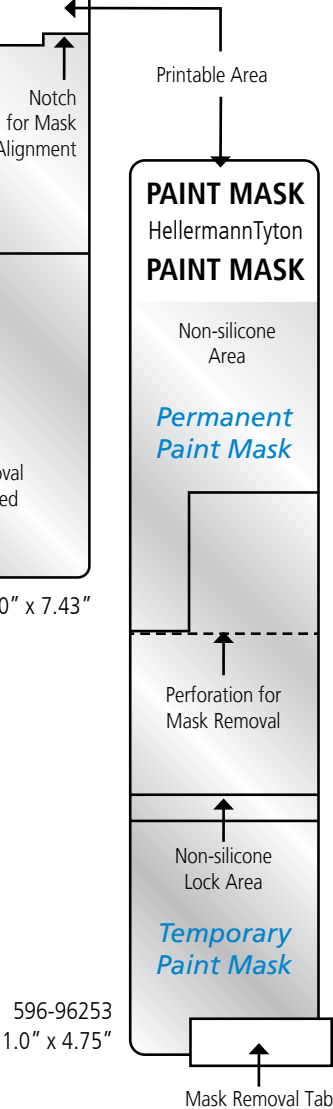

Identification

Foam Nameplate Labels

HellermannTyton

TRUE HEPA AIR CLEANER

Model No. 13520

Made in U.S.A. of US and Foreign Components
120V A.C., 60 Hz, 1.5A

Thermally Protected
Patent No. 4392

READ ALL INSTRUCTIONS BEFORE USING
UNPLUG BEFORE SERVICING



For Consumer Relations call 1-800-537-1512

596-00417 | 3" x 4"

596-00503
BLACK FOAM
NAMEPLATE LABEL

596-00503
1.06" x .49"

596-00500
WHITE FOAM
NAMEPLATE LABEL

596-00500
1.06" x .49"

START

596-00412
1.25" x 1.25"
.88" hole dia.

STOP

White Foam
Button Label
1.2mm hole
596-00414

596-00414 | 1.75" x 1.75"

596-00415

Foam Button Label

ON

OFF

Black Foam
Button Label
1.2mm hole
596-00415

596-00415 | 1.75" x 1.75"

UNLOCK

596-00413
1.25" x 1.25"
.88" hole dia.

596-00507

BLACK FOAM NAMEPLATE LABEL

TOGGLE SWITCH

596-00507 | 2" x 1"

**POWER
MODULE**


596-00504 | 2" x 1"

STOP






Identification

ShrinkTrak Labels

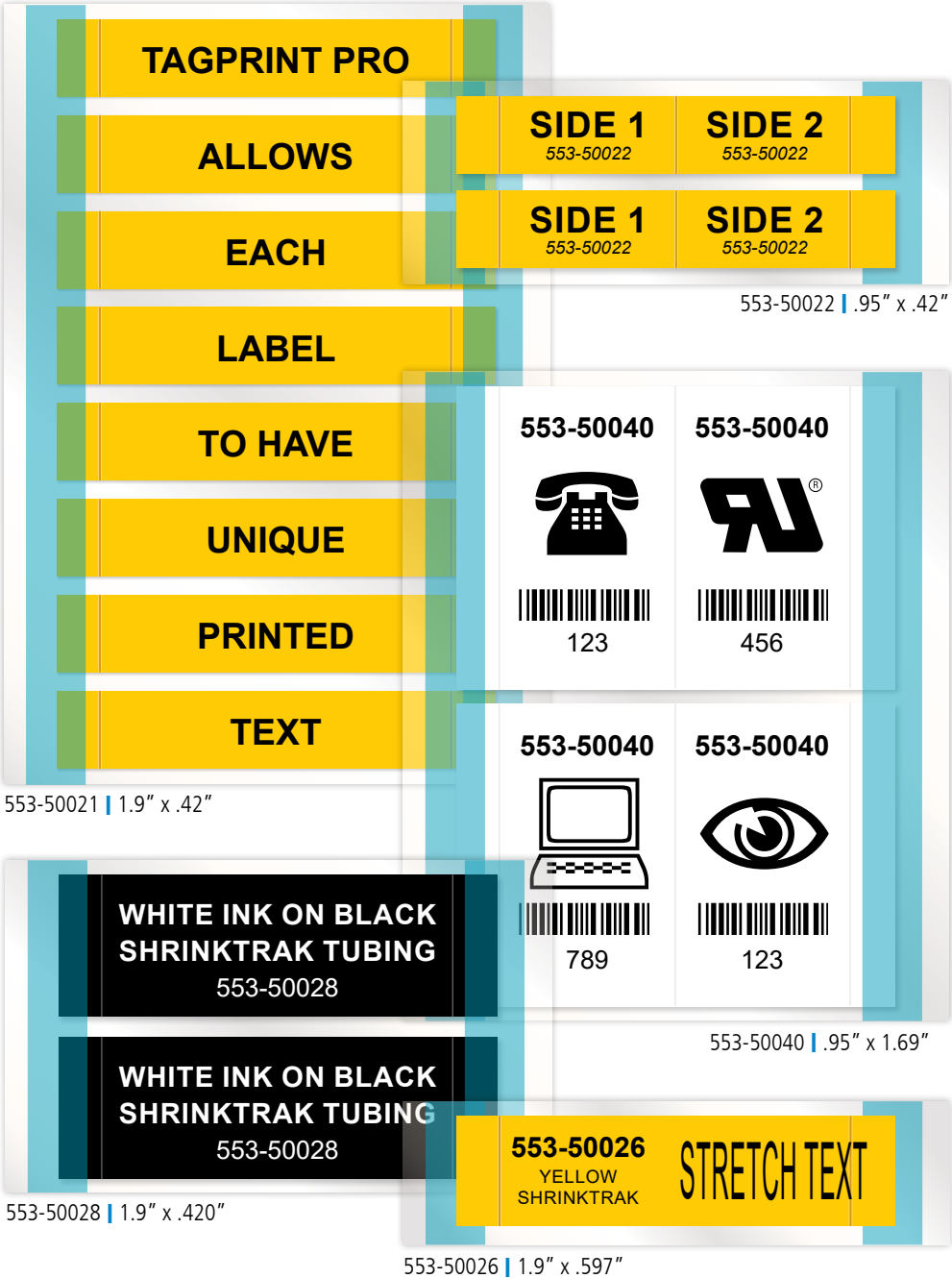



Identification

ShrinkTrak Labels

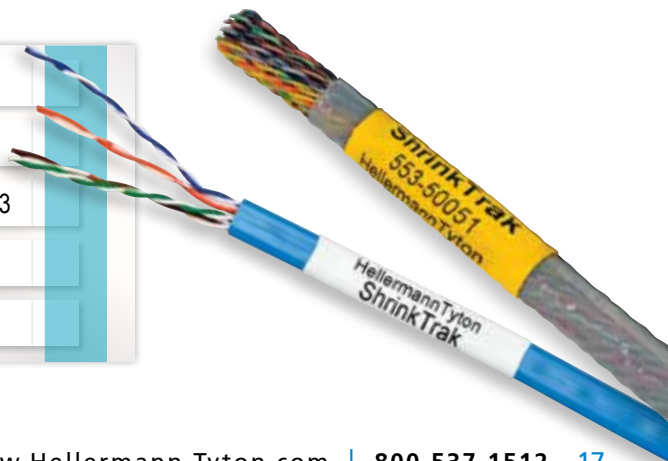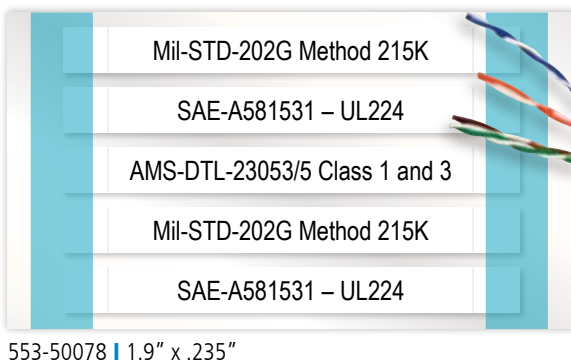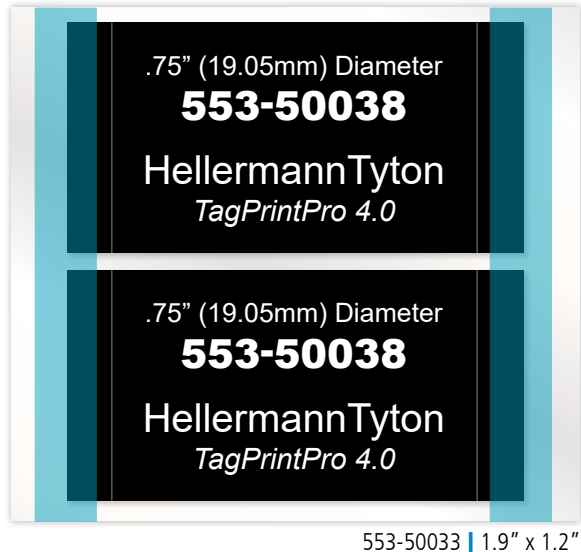


Identification


TipTag Labels

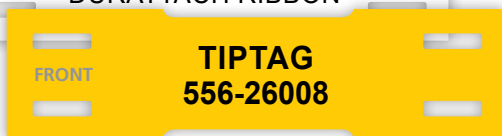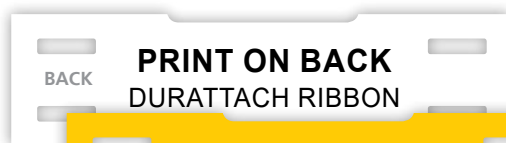


556-26008 | 2.59" x .68"

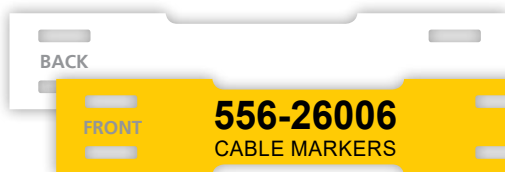

556-26006 | 2.59" x .50"

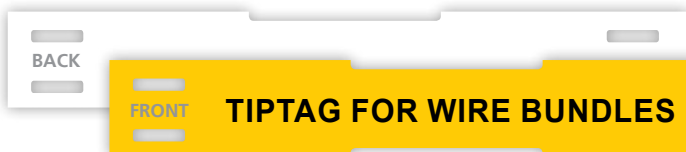

556-26007 | 3.54" x .50"

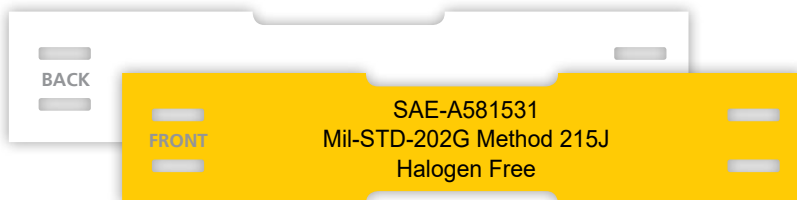


556-26009 | 3.54" x .68"




Identification

Pre-Printed Header Labels

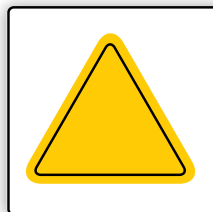

596-00378 | 1.35" x 2.75"

596-00376 | 2.75" x 5.5"

 


596-00386 | 1.35" x 2.75"

596-00388 | 2.75" x 5.5"



596-00379 | 1.35" x 2.75"

596-00377 | 2.75" x 5.5"

 

596-00387 | 1.35" x 2.75"

596-00389 | 2.75" x 5.5"



596-00203 | 4" x 6"

596-00424 | 3" x 2"



596-00621 | 4" x 6"

596-00622 | 3" x 2"



596-00427 | 4" x 6"

596-00425 | 3" x 2"




596-00204 | 4" x 6"

596-00426 | 3" x 2"



596-00371 | 4" x 6"

596-00372 | 3" x 2"

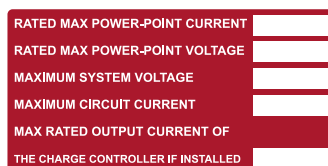

596-00253 | 4" x 2"

Identification

Banded Colored Continuous Rolls



WARNING

**Arc Flash &
Shock Hazard**

**Appropriate PPE
and Tools required
while working on
this equipment.**

Refer to NFPA 70 E.



CAUTION

**ENGINEERED SERIES
COMBINATION SYSTEM
RATED 50K AMPERES
IDENTIFIED REPLACEMENT
COMPONENTS REQUIRED**



558-00330 | 3" wide roll



558-00328 | 2" wide roll

Identification

Solid Colored Continuous Rolls

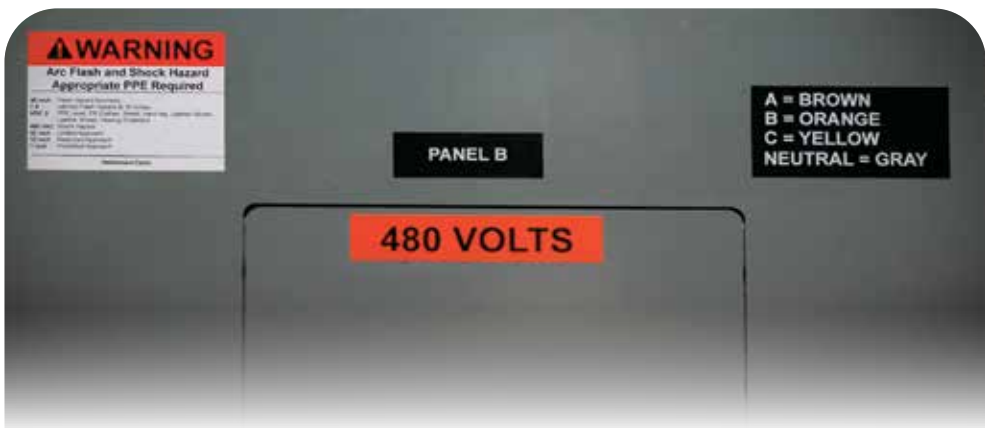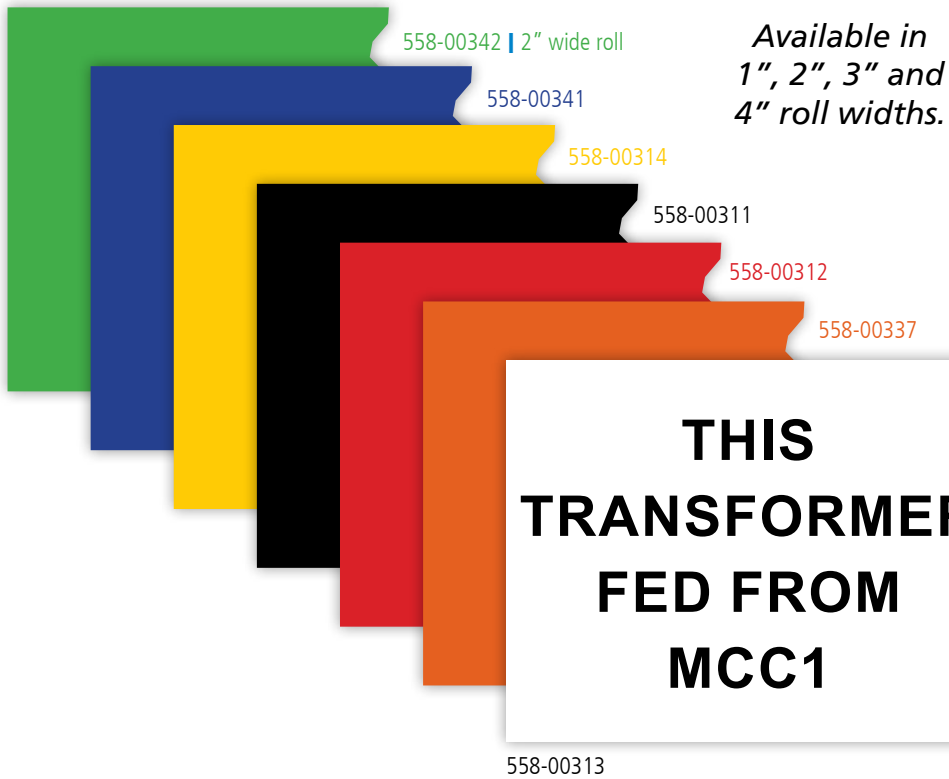

Identification

Thermal Transfer Labels

250 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Booklet Qty.
TYHCT-250	TYHCT-250	0.25 (6.4)	1.50 (38.1)	1.625 (41.27)	0.25 (6.35)	4.12 (104.70)	16	White	1
TAG21T6-250	TAG21T6	0.50 (12.7)	0.75 (19.1)	0.875 (22.22)	0.5 (12.7)	3.25 (82.55)	6	White	1
TAG11T4-250	TAG11T4	0.65 (16.5)	0.20 (5.1)	0.50 (12.7)	0.65 (16.51)	2.60 (66.04)	4	White	1
TAG28T4-250	TAG28T4	0.80 (20.3)	1.43 (36.3)	1.62 (41.1)	0.8 (20.3)	3.45 (87.60)	4	White	1
TAG15T3-250	TAG15T3	1.00 (25.4)	0.50 (12.7)	0.60 (15.24)	1.0 (25.40)	3.35 (85.09)	3	White	1
TAG35T2-250	TAG35T2	2.00 (50.8)	0.38 (9.5)	0.50 (12.7)	2.0 (50.8)	4.10 (104.14)	2	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

336 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Booklet Qty.
TAG96T1-336*	TAG96T1	1.90 (48.2)	0.25 (6.4)	0.375 (9.35)	1.9 (48.2)	2.00 (50.80)	1	White	1
TAG68T1-336*	TAG68T1	3.80 (96.5)	0.28 (7.0)	0.50 (12.7)	3.8 (96.5)	4.00 (101.60)	1	White	1
TAG69T1-336*	TAG69T1	2.00 (50.8)	0.28 (7.0)	0.50 (12.7)	2.0 (50.8)	2.13 (53.97)	1	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

795 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
TAG15T3-795*	TAG15T3	1.00 (25.4)	0.50 (12.7)	0.60 (15.24)	1.07 (27.17)	3.35 (85.09)	3	Silver (SR)	1
TAG27T1-795*	TAG27T1	1.50 (38.1)	0.75 (19.1)	0.875 (22.2)	1.50 (38.1)	2.20 (55.88)	1	Silver (SR)	1
TAG72T1-795*	TAG72T1	2.75 (69.9)	1.25 (31.0)	1.375 (34.93)	2.75 (69.85)	2.95 (74.95)	1	Silver (SR)	1
TAG73T1-795*	TAG73T1	2.00 (50.8)	1.00 (25.4)	1.12 (28.4)	2.0 (50.8)	2.20 (55.83)	1	Silver (SR)	1
TAG76T1-795*	TAG76T1	2.50 (63.5)	2.00 (50.8)	2.12 (53.8)	2.5 (63.5)	2.62 (66.50)	1	Silver (SR)	1
TAG78T1-795*	TAG78T1	3.00 (76.2)	4.00 (101.6)	4.12 (104.7)	3.0 (76.2)	3.12 (79.20)	1	Silver (SR)	1
TAG79T1-795*	TAG79T1	4.00 (101.6)	2.00 (50.8)	2.12 (53.97)	4.0 (101.6)	4.25 (107.90)	1	Silver (SR)	1
TAG80T1-795*	TAG80T1	3.00 (76.2)	5.00 (127.0)	5.12 (130.48)	3.0 (76.2)	3.13 (79.37)	1	Silver (SR)	1
TAG75T1-795*	TAG75T1	2.00 (50.8)	0.63 (15.9)	0.75 (19.05)	2.0 (50.8)	2.12 (53.80)	1	Silver (SR)	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Thermal Transfer Labels

822 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
TAG75T1-822*	TAG75T1	2.00 (50.8)	0.63 (15.9)	0.75 (19.05)	2.0 (50.8)	2.12 (53.80)	1	White	1
TAG81T8-822*	TAG81T8	0.32 (8.3)	0.20 (5.1)	0.32 (8.25)	0.32 (8.25)	2.60 (66.04)	8	White	1
TAG83T1-822*	TAG83T1	4.00 (101.6)	0.31 (7.9)	0.44 (11.13)	4.0 (101.6)	4.10 (104.14)	1	White	1
TAGPP1T6-822*	TAGPP1T6	0.63 (15.9)	0.33 (7.9)	0.75 (19.05)	0.63 (15.9)	3.80 (96.52)	6	White	1
TAGPP1T6-82210M*		0.63 (15.9)	0.33 (7.9)	0.75 (19.05)	.625 (15.87)	3.80 (96.52)	6	White	1
TAG11T4-822*	TAG11T4	0.65 (16.5)	0.20 (5.1)	0.50 (12.7)	0.65 (16.5)	2.60 (66.04)	4	White	1
TAG13T4-822*	TAG13T4	0.75 (19.1)	0.25 (6.4)	0.35 (8.89)	0.75 (19.05)	3.35 (85.09)	4	White	1
TAG15T3-822*	TAG15T3	1.00 (25.4)	0.50 (12.7)	0.60 (15.24)	1.07 (27.17)	3.35 (85.09)	3	White	1
TAG16T3-822*	TAG16T3	0.90 (22.9)	0.25 (6.4)	0.35 (8.89)	0.90 (22.9)	3.35 (85.09)	3	White	1
TAG27T1-822*	TAG27T1	1.50 (38.1)	0.75 (19.1)	0.875 (22.2)	1.50 (38.1)	2.20 (55.88)	1	White	1
TAG72T1-822*	TAG72T1	2.75 (69.8)	1.25 (31.0)	1.375 (34.93)	2.75 (69.85)	2.95 (74.95)	1	White	1
TAG70T12-822*	TAG70T12	0.25 (6.4)	0.25 (6.4)	0.50 (12.7)	.25 (6.4)	3.20 (81.20)	12	White	1
TAG71T5-822*	TAG71T5	0.50 (12.7)	0.43 (12.7)	0.66 (16.76)	0.50 (12.7)	3.35 (85.09)	5	White	1
TAG73T1-822*	TAG73T1	2.00 (50.8)	1.00 (25.4)	1.125 (28.57)	2.0 (50.8)	2.20 (55.83)	1	White	1
TAG82T2-822*	TAG82T2	1.50 (38.1)	0.25 (6.4)	0.30 (7.62)	1.50 (38.1)	3.20 (81.28)	2	White	1
TAG84T3-822*	TAG84T3	1.25 (31.8)	0.38 (31.8)	0.50 (12.7)	1.25 (31.75)	4.00 (101.60)	3	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

TAG17T2-822 is not recommended for TT10SM, TT210SM, TT300SM, TT310SM, or TT330SM printers. Use TAG82T2 instead.

822C Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
TAG27T1-822C	TAG27T1	1.50 (38.1)	0.75 (19.1)	0.875 (22.2)	1.50 (38.1)	2.20 (55.88)	1	Clear (CL)	1
TAG11T4-822C*	TAG11T4	0.65 (16.5)	0.20 (5.1)	0.50 (12.7)	0.65 (16.5)	2.60 (66.04)	4	Clear (CL)	1
TAGPP1T6-822C	TAGPP1T6	0.63 (15.9)	0.33 (7.9)	0.75 (19.05)	0.63 (15.9)	3.80 (96.52)	6	Clear (CL)	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Thermal Transfer Labels

840 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
596-73833*	PCP2X1	2.00 (50.8)	1.00 (25.4)	1.125 (28.57)	2.0 (50.8)	2.20 (122.90)	1	White	1
596-73834*	PCP3X1	3.00 (76.2)	1.00 (25.4)	1.125 (28.57)	3.0 (76.2)	3.20 (81.28)	1	White	1
596-73835*	PCP4X3	4.00 (101.6)	3.00 (76.2)	3.125 (79.37)	4.0 (101.6)	4.20 (106.68)	1	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

940 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
596-21251	TAG21T6	0.50 (12.7)	0.75 (19.1)	0.875 (22.22)	0.50 (12.7)	3.25 (82.55)	6	White	1
596-28251	TAG28T4	0.80 (20.3)	1.43 (36.3)	1.62 (41.1)	0.80 (20.3)	3.45 (87.60)	4	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

DTH Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Labels per Row	Color	Qty. per Roll
TAG16T3-DTH	TAG16T3	0.90 (22.9)	0.25 (6.4)	0.35 (8.89)	0.90 (22.9)	3.35 (85.09)	3	White	1
TAG15T3-DTH	TAG15T3	1.00 (25.4)	0.50 (12.7)	0.60 (15.24)	1.10 (27.94)	3.35 (85.09)	3	White	1
TAG73T1-DTH*	TAG73T1	2.00 (50.8)	1.00 (25.4)	1.125 (28.57)	2.0 (50.8)	2.20 (55.83)	1	White	1
TAG33T1-DTH	TAG33T1	3.00 (76.2)	2.00 (50.8)	2.125 (53.97)	3.0 (76.2)	3.10 (78.74)	1	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

For use with DTH ribbons only.

788C Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAGPP1-788C	TAGPP1	0.63 (15.9)	0.33 (8.5)	12	30	360	Clear	1000
TAGPP2-788C	TAGPP2	0.66 (16.7)	0.33 (8.4)	12	30	360	Clear	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

CIJ4800 Color Printer Inkjet Labels

CIJ4800 Continuous Inkjet Printable Labels

PART NO.	TYPE	Label Width (W) in. (mm)	Roll Length (L) ft. (m)	Color	Pkg. Qty.
558-00399	HT1WT25125	1.0 (25.4)	125 (38.1)	White	1
558-00396	HT2WT50125	2.0 (50.8)	125 (38.1)	White	1
558-00397	HT3WT76125	3.0 (76.2)	125 (38.1)	White	1
558-00398	HT4WT101125	4.0 (101.6)	125 (38.1)	White	1
558-00412	HTIAR4X25	4.0 (101.6)	25 (7.62)	White	1
558-00413	HT1WTP25125	1.0 (25.4)	125 (38.1)	White	1
558-00414	HT2WTP50125	2.0 (50.8)	125 (38.1)	White	1
558-00415	HT3WTP76125	3.0 (76.2)	125 (38.1)	White	1
558-00416	HT4WTP101125	4.0 (101.6)	125 (38.1)	White	1
558-00700	HT2WT50RP100	2.0 (50.8)	100 (38.1)	White	1
558-00701	HT3WHT76RP100	3.0 (76.2)	100 (38.1)	White	1
558-00702	HT4WT101RP100	4.0 (101.6)	100 (38.1)	White	1

CIJ4800 Die Cut Inkjet Labels

PART NO.	TYPE	Width (W) in. (mm)	Height (H) in. (mm)	Color	Qty. per Roll
558-10000	HT225X45IJWP	2.2 (57.1)	4.5 (114.3)	White	75
558-10001	HT35X5IJWP	3.5 (88.9)	5.0 (127.0)	White	50
558-10002	HT4X2IJWP	4.0 (101.6)	2.0 (50.8)	White	150
558-10003	HT4X4IJWP	4.0 (101.6)	4.0 (101.6)	White	75
558-10004	HT4X6IJWP	4.0 (101.6)	6.0 (152.4)	White	50

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Self-Laminating Labels

Thermal Transfer Self-Laminating Labels

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Color	Roll Qty.
TAG26T6-100B*	TAG26T6	0.5 (12.7)	0.4 (9.5)	1.0 (25.4)	0.5 (12.7)	3.4 (85.1)	White	1
TAG2T5-100B*	TAG2T5	0.5 (12.7)	0.5 (12.7)	1.6 (41.3)	0.7 (16.8)	3.4 (85.1)	White	1
TAG51T3-100B*	TAG51T3	1.0 (25.4)	0.4 (8.9)	0.9 (23.7)	1.1 (27.2)	3.4 (85.1)	White	1
TAG22T2-100B*	TAG22T2	1.0 (25.4)	0.5 (12.7)	1.6 (41.3)	1.1 (27.2)	2.3 (57.1)	White	1
TAG22T3-100B*	TAG22T3	1.0 (25.4)	0.5 (12.7)	1.6 (41.3)	1.1 (27.2)	3.4 (85.1)	White	1
TAG9T3-100B*	TAG9T3	1.0 (25.4)	1.0 (25.4)	2.5 (63.5)	1.1 (27.2)	3.4 (85.1)	White	1
TAG3T3-100B*	TAG3T3	1.0 (25.4)	1.0 (25.4)	4.0 (101.6)	1.0 (25.4)	3.4 (85.1)	White	1
TAG38T4-100B*	TAG38T4	1.0 (25.4)	1.5 (38.1)	7.8 (196.8)	1.0 (25.4)	4.1 (104.1)	White	1
TAG53T2-100B*	TAG53T2	1.5 (38.1)	0.7 (17.8)	1.6 (41.3)	1.5 (38.1)	3.4 (89.1)	White	1
TAG1T1-100B*	TAG1T1	1.9 (48.3)	0.8 (19.1)	3.4 (86.8)	2.0 (50.8)	3.9 (98.4)	White	1
TAG24T1-100B*	TAG24T1	2.0 (50.8)	0.5 (12.7)	1.7 (42.6)	2.0 (50.8)	2.2 (55.9)	White	1
TAG10T2-100B*	TAG10T2	2.0 (50.8)	0.8 (19.1)	2.5 (63.5)	2.0 (50.8)	3.9 (98.4)	White	1
TAG7T1-100B*	TAG7T1	2.0 (50.8)	1.5 (38.1)	7.8 (196.8)	2.0 (50.8)	4.1 (104.1)	White	1
TAG6T1-100B*	TAG6T1	2.0 (50.8)	1.0 (25.4)	4.0 (101.6)	2.0 (50.8)	2.2 (55.9)	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Laser Tag Self-Laminating Labels

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Color	Roll Qty.
TAG26L-105	TAG26L	0.5 (12.7)	0.4 (9.5)	0.8 (19.0)	1.9 (48.2)	8.5 (215.0)	White	1
TAG2L-105	TAG2L	0.5 (12.7)	0.5 (12.7)	1.4 (36.4)	0.5 (12.7)	8.5 (215.0)	White	1
TAG5L-105	TAG5L	0.8 (20.3)	0.5 (12.7)	1.4 (36.4)	0.9 (22.9)	8.5 (215.0)	White	1
TAG65L-105	TAG65L	0.8 (20.7)	0.8 (20.7)	2.1 (53.9)	0.8 (20.6)	8.5 (215.0)	White	1
TAG51L-105	TAG51L	1.0 (25.4)	0.4 (8.9)	0.8 (19.0)	1.0 (20.3)	8.5 (215.0)	White	1
TAG49L-105	TAG49L	1.0 (25.4)	0.4 (8.9)	1.0 (25.4)	1.0 (25.4)	8.5 (215.0)	White	1
TAG63L-105	TAG63L	1.0 (25.4)	0.5 (12.7)	1.3 (33.7)	1.0 (25.4)	8.5 (215.0)	White	1
TAG9L-105	TAG9L	1.0 (25.4)	1.0 (25.4)	2.3 (57.1)	1.1 (27.9)	8.5 (215.0)	White	1
TAG50L-105	TAG50L	1.0 (25.4)	1.0 (25.4)	3.2 (80.4)	1.0 (25.4)	8.5 (215.0)	White	1
TAG64L-105	TAG64L	1.2 (29.7)	0.8 (21.1)	3.3 (84.6)	1.2 (29.7)	8.5 (215.0)	White	1
TAG1L-105	TAG1L	1.9 (48.2)	0.8 (19.1)	3.4 (85.1)	2.0 (50.8)	8.5 (215.0)	White	1
TAG52L-105	TAG52L	2.0 (50.8)	0.5 (11.9)	1.3 (33.7)	2.0 (50.8)	8.5 (215.0)	White	1
TAG10L-105	TAG10L	2.0 (50.8)	0.8 (19.1)	2.3 (57.2)	2.0 (50.8)	8.5 (215.0)	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Self-Laminating Labels

Self-Laminating Inkjet Labels

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Height (H) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Color	Roll Qty.
TAG26J-994	TAG26J	0.5 (12.7)	0.4 (8.9)	0.8 (19.0)	0.5 (12.7)	8.5 (215.9)	White	1
TAG5J-994	TAG5J	0.8 (20.3)	0.5 (12.7)	1.4 (36.3)	0.8 (20.3)	8.5 (215.0)	White	1
TAG22J-994	TAG22J	1.0 (25.4)	0.5 (12.7)	1.4 (36.3)	1.0 (25.4)	8.5 (215.0)	White	1
TAG9J-994	TAG9J	1.0 (25.4)	0.8 (19.1)	2.3 (57.2)	1.0 (25.4)	8.5 (215.0)	White	1
TAG64J-994	TAG64J	1.2 (29.6)	0.9 (21.8)	3.3 (82.6)	1.2 (29.6)	8.5 (215.0)	White	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Paintmask Labels

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Height in. (mm)	Label Height (H) in. (mm)	Min. Bundle Diameter in. (mm)	Max. Bundle Diameter in. (mm)	Liner Width in. (mm)	Qty per Roll
596-96255	PW.25W1P	1.00 (25.4)	0.75 (19.1)	0.75 (19.0)	0.13 (3.2)	0.38 (9.5)	2.00 (50.8)	1
596-96253	PW.25W1	1.00 (25.4)	0.75 (19.1)	0.75 (19.0)	0.13 (3.2)	0.38 (9.5)	2.00 (50.8)	1
596-96260	PW.50W1	1.00 (25.4)	1.50 (38.1)	1.50 (38.1)	0.38 (9.5)	0.63 (15.8)	3.00 (76.2)	1
596-96261	PW.50W1P	1.00 (25.4)	1.50 (38.1)	1.50 (38.1)	0.38 (9.5)	0.63 (15.8)	3.00 (76.2)	1
596-96262	PW2.75W1	1.00 (25.4)	1.50 (38.1)	1.50 (38.1)	0.63 (15.8)	0.88 (22.2)	2.38 (60.4)	1
596-96263	PW2.75W1P	1.00 (25.4)	1.50 (38.1)	1.50 (38.1)	0.63 (15.8)	0.88 (22.2)	2.38 (60.4)	1
596-96256	PW.50W2P	2.00 (50.8)	1.50 (38.1)	1.50 (38.1)	0.38 (9.5)	0.63 (15.8)	3.00 (76.2)	1
596-96254	PW.50W2	2.00 (50.8)	1.50 (38.1)	1.50 (38.1)	0.38 (9.5)	0.63 (15.8)	3.00 (76.2)	1
596-96258	PW2.75W2P	2.00 (50.8)	1.50 (38.1)	1.50 (38.1)	0.63 (15.8)	0.88 (22.2)	4.20 (106.6)	1
596-96257	PW2.75W2	2.00 (50.8)	1.50 (38.1)	1.50 (38.1)	0.63 (15.8)	0.88 (22.2)	4.20 (106.6)	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

0.125" Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50088	HST3-1WH-3S	0.13 (3.2)	0.48 (12.1)	0.24 (5.7)	3-Slit	White	4000
553-50078	HST3-1WH	0.13 (3.2)	1.90 (48.3)	0.24 (5.7)	Unslit	White	2500
553-50077	HST3-1YE-2S	0.13 (3.2)	0.63 (16.0)	0.24 (5.7)	2-Slit	Yellow	3000
553-50075	HST3-1WH-2S	0.13 (3.2)	0.63 (16.0)	0.24 (5.7)	2-Slit	White	3000
553-50074	HST3-1WH-S	0.13 (3.2)	0.95 (24.1)	0.24 (5.7)	1-Slit	White	2000
553-50063	HST3-1WH-3S	0.13 (3.2)	0.48 (12.1)	0.24 (5.7)	3-Slit	White	1000
553-50007	HST3-1YE-S	0.13 (3.2)	0.95 (24.1)	0.24 (5.7)	Unslit	Yellow	500
553-50005	HST3-1YE	0.13 (3.2)	1.90 (48.3)	0.24 (5.7)	Unslit	Yellow	250
553-50004	HST3-1WH-S	0.13 (3.2)	0.95 (24.1)	0.24 (5.7)	1-Slit	White	500
553-50003	HST3-1WH	0.13 (3.2)	1.90 (48.3)	0.24 (5.7)	Unslit	White	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

0.187 " Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50176	HST4.8-1.6WH-S	0.19 (4.7)	0.95 (24.1)	0.31 (7.9)	1-Slit	White	3000
553-50081	HST4.8-1.6WH-3S	0.19 (4.7)	0.48 (12.1)	0.31 (7.9)	3-Slit	White	4000
553-50080	HST4.8-1.6WH-S	0.19 (4.7)	0.95 (24.1)	0.31 (7.9)	1-Slit	White	2000
553-50079	HST4.8-1.6WH	0.19 (4.7)	1.90 (48.3)	0.31 (7.9)	Unslit	White	5000
553-50072	HST4.8-1.6WH-2S	0.19 (4.7)	0.63 (16.1)	0.31 (7.9)	2-Slit	White	3000
553-50068		0.19 (4.7)	0.63 (16.0)	0.31 (7.9)	2-Slit	White	750
553-50064	HST4.8-1.6WH-3S	0.19 (4.7)	0.48 (12.1)	0.31 (7.9)	3-Slit	White	1000
553-50014	HST4.8-1.6YE-S	0.19 (4.7)	0.95 (24.1)	0.31 (7.9)	1-Slit	Yellow	500
553-50012	HST4.8-1.6YE	0.19 (4.7)	1.90 (48.3)	0.31 (7.9)	Unslit	Yellow	250
553-50011	HST4.8-1.6WH-S	0.19 (4.7)	0.95 (24.1)	0.31 (7.9)	1-Slit	White	500
553-50010	HST4.8-1.6WH	0.19 (4.7)	1.90 (48.3)	0.31 (7.9)	Unslit	White	1000
553-50009		0.19 (4.7)	1.90 (48.3)	0.31 (7.9)	Unslit	White	250
553-50008	HST4.8-1.6BK	0.19 (4.7)	1.90 (48.3)	0.31 (7.9)	Unslit	Black	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

ShrinkTrak Markers

0.25 " Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50089	HST6-2WH-3S	0.25 (6.4)	0.48 (12.1)	0.42 (10.7)	3-Slit	White	4000
553-50085	HST6-2YE-S	0.25 (6.4)	0.95 (24.1)	0.42 (10.7)	1-Slit	Yellow	2000
553-50084	HST6-2WH-S	0.25 (6.4)	0.95 (24.1)	0.42 (10.7)	1-Slit	White	2000
553-50082	HST6-2WH-2S	0.25 (6.4)	0.63 (16.1)	0.42 (10.7)	2-Slit	White	750
553-50022	HST6-2YE-S	0.25 (6.4)	0.95 (24.1)	0.42 (10.7)	1-Slit	Yellow	500
553-50020	HST6-2YE	0.25 (6.4)	1.90 (48.3)	0.42 (10.7)	Unslit	Yellow	250
553-50019	HST6-2WH-S	0.25 (6.4)	0.95 (24.1)	0.42 (10.7)	1-Slit	White	500
553-50018	HST6-2WH	0.25 (6.4)	1.90 (48.3)	0.42 (10.7)	Unslit	White	5000
553-50017		0.25 (6.4)	1.90 (48.3)	0.42 (10.7)	Unslit	White	1000
553-50016		0.25 (6.4)	1.90 (48.3)	0.42 (10.7)	Unslit	White	250
553-50015	HST6-2BK	0.25 (6.4)	1.90 (48.3)	0.42 (10.7)	Unslit	Black	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

0.375 " Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50192	HST9-3WH	0.38 (9.5)	1.90 (48.3)	0.60 (15.2)	Unslit	White	1000
553-50066	HST9-3WH-3S	0.38 (9.5)	0.48 (12.1)	0.60 (15.2)	3-Slit	White	1000
553-50027	HST9-3YE-S	0.38 (9.5)	0.95 (24.1)	0.60 (15.2)	1-Slit	Yellow	500
553-50026	HST9-3YE	0.38 (9.5)	1.90 (48.3)	0.60 (15.2)	Unslit	Yellow	250
553-50025	HST9-3WH-S	0.38 (9.5)	0.95 (24.1)	0.60 (15.2)	1-Slit	White	500
553-50024	HST9-3WH	0.38 (9.5)	1.90 (48.3)	0.60 (15.2)	Unslit	White	250
553-50023	HST9-3BK	0.38 (9.5)	1.90 (48.3)	0.60 (15.2)	Unslit	Black	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

0.5 " Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50086	HST12-4WH-4S	0.50 (12.7)	0.48 (12.1)	0.77 (19.6)	3-Slit	White	1000
553-50032	HST12-4YE-S	0.50 (12.7)	0.95 (24.1)	0.77 (19.6)	1-Slit	Yellow	500
553-50031	HST12-4YE	0.50 (12.7)	1.90 (48.3)	0.77 (19.6)	Unslit	Yellow	250
553-50030	HST12-4WH-S	0.50 (12.7)	0.95 (24.1)	0.77 (19.6)	1-Slit	White	500
553-50029	HST12-4WH	0.50 (12.7)	1.90 (48.3)	0.77 (19.6)	Unslit	White	250
553-50028	HST12-4BK	0.50 (12.7)	1.90 (48.3)	0.77 (19.6)	Unslit	Black	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

ShrinkTrak Markers

0.75 " Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50037	HST18-6YE-S	0.75 (19.1)	0.95 (24.1)	1.20 (30.5)	1-Slit	Yellow	500
553-50036	HST18-6YE	0.75 (19.1)	1.90 (48.3)	1.20 (30.5)	Unslit	Yellow	250
553-50035	HST18-6WH-S	0.75 (19.1)	0.95 (24.1)	1.20 (30.5)	1-Slit	White	500
553-50034	HST18-6WH	0.75 (19.1)	1.90 (48.3)	1.20 (30.5)	Unslit	White	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

1.0" Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50042	HST24-8YE-S	1.00 (25.4)	0.95 (24.1)	1.69 (42.9)	Single	Yellow	500
553-50041	HST24-8YE	1.00 (25.4)	1.90 (48.3)	1.69 (42.9)	Unslit	Yellow	250
553-50040	HST24-8WH-S	1.00 (25.4)	0.95 (24.1)	1.69 (42.9)	1-Slit	White	500
553-50039	HST24-8WH	1.00 (25.4)	1.90 (48.3)	1.69 (42.9)	Unslit	White	250
553-50038	HST24-8BK	1.00 (25.4)	1.90 (48.3)	1.69 (42.9)	Unslit	Black	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

1.5" Outside Diameter

PART NO.	TYPE	Outside Diameter (D) in. (mm)	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Center Slit	Color	Qty per Box
553-50225	HFST39-13YE	1.50 (38.1)	1.90 (48.3)	2.26 (57.4)	Unslit	Yellow	150
553-50209	HST39-13WH	1.50 (38.1)	1.90 (48.3)	2.26 (57.4)	Unslit	White	150

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Foam Nameplates, TipTags

Foam Nameplates

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Color	Qty per Roll
596-00503	NPL27X13BK	1.06 (27.0)	0.49 (11.4)	Black	500
596-00500	NPL27X13WH	1.06 (27.0)	0.49 (11.4)	White	500
596-00507	NPL51X25BK	2.00 (50.8)	1.00 (25.4)	Black	500
596-00504	NPL51X25WH	2.00 (50.8)	1.00 (25.4)	White	500
596-00417	NPL76X101WH	3.00 (76.2)	4.00 (101.6)	White	150

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Foam Button Nameplates

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Mounting Hole Dia. in. (mm)	Color	Qty per Roll
596-00915	NPLH31X48WH22.5	1.20 (30.5)	1.90 (30.5)	0.88 (22.4)	White	250
596-00413	NPLH31X31BK22.5	1.25 (31.7)	1.25 (31.7)	0.88 (22.4)	Black	250
596-00412	NPLH31X31WH22.5	1.25 (31.7)	1.25 (31.7)	0.88 (22.4)	White	250
596-00415	NPLH44X44BK30.5	1.75 (44.4)	1.75 (44.4)	1.20 (30.5)	Black	250
596-00414	NPLH44X44WH30.5	1.75 (44.4)	1.75 (44.4)	1.20 (30.5)	White	250
596-00202	NPL60X60YE	2.38 (60.3)	2.38 (60.3)	1.20 (30.5)	Yellow	100

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

TipTags

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Width in. (mm)	Printable Area Height in. (mm)	Qty. per Box
556-26006	TIPTAGVA10X65YEW	2.59 (65.0)	2.6 (65.0)	0.4 (10.0)	500
556-26007	TIPTAGVA10X90YEW	3.54 (90.0)	3.5 (90.0)	0.4 (10.0)	500
556-26008	TIPTAGVA15X65YEW	2.59 (65.0)	2.6 (65.0)	0.6 (15.0)	500
556-26009	TIPTAGVA15X90YEW	3.54 (90.0)	3.5 (90.0)	0.6 (15.0)	500

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Pre-Printed Signal Word Labels on Rolls

For Indoor Use

PART NO.	TYPE	Description	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Color	Qty per Pkg
596-00378	WV275X135	WARNING Header, Orange with Blank Yellow Triangle	2.75 (69.9)	1.35 (34.3)	Orange	250
596-00379	DV275X135	WARNING Header, Red with Blank Yellow Triangle	2.75 (69.9)	1.35 (34.3)	Red	250
596-00386	WS275X135	WARNING Header, White with Orange	2.75 (69.9)	1.35 (34.3)	Orange	250
596-00387	DS275X135	DANGER Header, White with Red	2.75 (69.9)	1.35 (34.3)	Red	250
596-00372	3X2SAFETY	SAFETY Header, White with Green	3.00 (76.2)	2.00 (50.4)	Green	250
596-00424	3X2DANGER	DANGER Header, White with Red	3.00 (76.2)	2.00 (50.8)	Red	250
596-00425	3X2CAUTION	Yellow CAUTION header	3.00 (76.2)	2.00 (50.8)	Yellow	250
596-00426	3X2NOTICE	NOTICE Header, White with Blue	3.00 (76.2)	2.00 (50.8)	Blue	250
596-00622	3X2WARNING	WARNING Header, Black with Orange	3.00 (76.2)	2.00 (50.8)	Orange	250
596-00376	WV55X275	WARNING Header, White with Orange	5.50 (139.7)	2.75 (69.9)	Orange	250
596-00377	DV55X275	DANGER Header, White with Red	5.50 (139.7)	2.75 (69.9)	Red	250
596-00388	WS55X275	WARNING Header, Black with Orange	5.50 (139.7)	2.75 (69.9)	Orange	250
596-00389	DS55X275	DANGER Header, White with Red	5.50 (139.7)	2.75 (69.9)	Red	250
596-00203	4X6DANGER	DANGER Header, White with Red	6.00 (152.4)	4.00 (101.6)	Red	250
596-00204	4X6NOTICE	NOTICE Header, White with Blue	6.00 (152.4)	4.00 (101.6)	Blue	250
596-00371	4X6SAFETY	SAFETY Header, White with Green	6.00 (152.4)	4.00 (101.6)	Green	250
596-00427	4X6CAUTION	CAUTION Header, Black with Yellow	6.00 (152.4)	4.00 (101.6)	Yellow	250
596-00621	4X6WARNING	WARNING Header, Black with Orange	6.00 (152.4)	4.00 (101.6)	Orange	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Pre-Printed Signal Word Labels on Rolls

For Outdoor Use

PART NO.	TYPE	Description	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Color	Qty per Pkg
596-00644	WV275X135UV	Orange WARNING header, yellow voltage safety symbol	1.35 (34.3)	2.75 (69.9)	Orange	250
596-00645	WV55X275UV	Orange WARNING header, yellow voltage safety symbol	2.75 (69.9)	5.50 (139.7)	Orange	250
596-00634	3X2WARNINGUV	Orange WARNING header	3.00 (76.2)	2.00 (50.8)	Orange	250
596-00635	3X2CAUTIONUV	Yellow CAUTION header	3.00 (76.2)	2.00 (50.8)	Yellow	250
596-00648	3X2DANGERUV	Red DANGER header	3.00 (76.2)	2.00 (50.8)	Red	250
596-00633	4X6WARNINGUV	Orange WARNING header	6.00 (152.4)	4.00 (101.6)	Orange	250
596-00646	4X6DANGERUV	Red DANGER header	6.00 (152.4)	4.00 (101.6)	Red	250
596-00636	4X6CAUTIONUV	Yellow CAUTION header	6.00 (152.4)	4.00 (101.6)	Yellow	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Reflective Solid Colored

PART NO.	TYPE	Label Width (W) in. (mm)	Roll Length (L) ft (m)	Color	Roll Qty.
558-00372	HT2RDRF250	2.00 (50.8)	250.0 (76.2)	Red Reflective	250
558-00373	HT3RDRF250	3.00 (76.2)	100.0 (30.5)	Red Reflective	100

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Color Banded Continuous Vinyl Rolls

PART NO.	TYPE	Label Width (W) in. (mm)	Roll Length (L) ft (m)	Color	Roll Qty.
558-00328	HT2YE50250	2.00 (50.8)	250.0 (76.2)	Yellow	250
558-00327	HT2OE50250	2.00 (50.8)	250.0 (76.2)	Orange	250
558-00331	HT3YE75250	3.00 (76.2)	250.0 (76.2)	Yellow	250
558-00330	HT3OE75250	3.00 (76.2)	250.0 (76.2)	Orange	250
558-00334	HT4YE10250	4.00 (101.6)	250.0 (76.2)	Yellow	250
558-00333	HT4OE10250	4.00 (101.6)	250.0 (76.2)	Orange	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Continuous Vinyl Rolls

Solid Colored

PART NO.	TYPE	Label Width (W) in. (mm)	Roll Length (L) ft (m)	Color	Roll Qty.
558-00340	HT1GN250	1.00 (25.4)	250.0 (76.2)	Green	250
558-00339	HT1BU250	1.00 (25.4)	250.0 (76.2)	Blue	250
558-00336	HT1OE250	1.00 (25.4)	250.0 (76.2)	Orange	250
558-00310	HT1YE250	1.00 (25.4)	250.0 (76.2)	Yellow	250
558-00309	HT1WH250	1.00 (25.4)	250.0 (76.2)	White	250
558-00308	HT1RD250	1.00 (25.4)	250.0 (76.2)	Red	250
558-00307	HT1BK250	1.00 (25.4)	250.0 (76.2)	Black	250
558-00342	HT2GN250	2.00 (50.8)	250.0 (76.2)	Green	250
558-00341	HT2BU250	2.00 (50.8)	250.0 (76.2)	Blue	250
558-00337	HT2OE250	2.00 (50.8)	250.0 (76.2)	Orange	250
558-00314	HT2YE250	2.00 (50.8)	250.0 (76.2)	Yellow	250
558-00313	HT2WH250	2.00 (50.8)	250.0 (76.2)	White	250
558-00312	HT2RD250	2.00 (50.8)	250.0 (76.2)	Red	250
558-00311	HT2BK250	2.00 (50.8)	250.0 (76.2)	Black	250
558-00374	HT3BK250	3.00 (76.2)	250.0 (76.2)	Black	250
558-00373	HT3RDRF250	3.00 (76.2)	100.0 (30.5)	Red Reflective	100
558-00346	HT3YE250	3.00 (76.2)	250.0 (76.2)	Yellow	250
558-00345	HT3WH250	3.00 (76.2)	250.0 (76.2)	White	250
558-00343	HT3BU250	3.00 (76.2)	250.0 (76.2)	Blue	250
558-00338	HT3OE250	3.00 (76.2)	250.0 (76.2)	Orange	250
558-00006	HT3RD250	3.00 (76.2)	250.0 (76.2)	Red	250
558-00370	HT4RD250	4.00 (101.6)	250.0 (76.2)	Red	250
558-00351	HT4GN250	4.00 (101.6)	250.0 (76.2)	Green	250
558-00350	HT4WH250	4.00 (101.6)	250.0 (76.2)	White	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Laser Tag Labels

788 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAGPP1-788	TAGPP1L	0.63 (15.9)	0.37 (9.4)	12	30	360	White	1000
TAG62L-788	TAG62L	1.50 (38.1)	0.38 (9.5)	5	25	125	White	1000
TAG61L-788	TAG61L	2.62 (66.7)	1.00 (25.4)	3	10	30	White	7500
TAG60L-788	TAG60L	2.83 (71.9)	1.50 (38.1)	3	7	21	White	5250
TAG59L-788	TAG59L	4.00 (101.6)	1.50 (38.1)	2	7	14	White	3500
TAG55L-788	TAG55L	4.25 (107.9)	5.50 (139.7)	2	2	4	White	1000
TAG54L-788	TAG54L	8.50 (215.9)	5.50 (139.7)	1	2	2	White	500
TAG53L-788	TAG53L	8.50 (215.9)	10.81 (274.6)	1	1	1	White	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

789 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAG11L-789	TAG11L	0.65 (16.5)	0.20 (5.1)	10	48	480	White	5000
TAG13L-789	TAG13L	0.75 (19.1)	0.25 (6.4)	8	39	312	White	5000
TAG15L-789	TAG15L	1.00 (25.4)	0.50 (12.7)	7	19	133	White	5000
TAG14L-789	TAG14L	1.00 (25.4)	0.38 (9.5)	7	25	175	White	5000
TAG62L-788	TAG62L	1.50 (38.1)	0.38 (9.5)	5	25	125	White	1000
TAG96L-789	TAG96L	1.88 (47.6)	0.25 (6.4)	4	36	144	White	1000
TAG69L-789	TAG69L	2.00 (50.8)	0.28 (7.0)	4	35	140	White	5000
TAG67L-789	TAG67L	2.87 (73.0)	2.87 (73.0)	2	25	50	White	1000
TAG66L-789	TAG66L	3.59 (91.4)	0.38 (9.5)	2	25	50	White	1000
TAG68L-789	TAG68L	3.80 (96.5)	0.28 (7.0)	2	35	70	White	2500
TAG45L-789	TAG45L	4.00 (101.6)	0.80 (20.3)	2	12	24	White	5000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Cardstock

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAGPHONE	TAGPHONE	1.75 (44.5)	0.38 (9.5)	4	21	84	White	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

Inkjet Labels

108 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAGPP1J-108	TAGPP1J	0.63 (15.9)	0.31 (7.9)	12	30	360	White	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

450 Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAG19J-450	TAG19J	0.38 (9.5)	2.00 (50.8)	15	4	60	Black	1000
TAG21J-450	TAG21J	0.50 (12.7)	0.75 (19.1)	13	12	156	White	5000
TAG15J-450	TAG15J	0.50 (12.7)	1.00 (25.4)	13	9	117	Black	5000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Cardstock Material

PART NO.	TYPE	Label Width (W) in. (mm)	Label Height (H) in. (mm)	Labels per Row	Labels per Column	Labels per Sheet	Color	Qty per Pkg
TAGPHONE	TAGPHONE	1.75 (44.5)	0.38 (9.5)	4	21	84	White	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Printer Ribbons and Inks

PART NO.	TYPE	Description	Color	Pkg. Qty.
593-12000	PBIJC	Color Inkjet Ink Cartridge, Pigment Based	Various	1
TT822OUT	TT822OUT 110MM	Black Ribbon, 4.33" x 984', 1" Core, Polyester Film	Black	1
TT822OUTSM	TT822OUTSM	Black Ribbon, 4.33" x 242', 1/2" Core, Hard Resin Polyester Film	Black	1

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Identification

TagPrint® Pro 4.0

PART NO.	TYPE	Description
556-00035	TAGPRINT4	TagPrint Pro 4.0, Single User License
556-00036	TAGPRINT3LIC	TagPrint Pro 4.0, 3 License Network Program
556-00037	TAGPRINT5LIC	TagPrint Pro 4.0, 5 License Network Program
556-00038	TAGPRINT10LIC	TagPrint Pro 4.0, 10 License Network Program
556-00039	TAGPRINT25LIC	TagPrint Pro 4.0, 25 License Network Program
556-00052	TAGPRINT50LIC	TagPrint Pro 4.0, 50 License Network Program
556-00042	TAGPRINT3UPGRD	TagPrint Pro 4.0, Upgrade, TagPrint 2.0 Serial # Required
556-00043	TAGPRINT3UPGRD3S	TagPrint Pro 4.0, Upgrade, 1 User to 3 User
556-00044	TAGPRINT3UPGRD5S	TagPrint Pro 4.0, Upgrade, 3 User to 5 User
556-00045	TAGPRINT3UPGRD10S	TagPrint Pro 4.0, Upgrade, 5 User to 10 User
556-00046	TAGPRINT3UPGRD25S	TagPrint Pro 4.0, Upgrade, 10 User to 25 User

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

HellermannTyton

HellermannTyton North American Corporate Headquarters

7930 N. Faulkner Rd, PO Box 245017, Milwaukee, WI 53224-9517
Phone: (414) 355-1130, (800) 537-1512, Fax: (414) 355-7341, (800) 848-9866
email: corp@htamericas.com, www.hellermann.tyton.com

IATF 16949, ISO 9001, and ISO14001 certified

HellermannTyton Canada

Unit #4, 205 Industrial Parkway North, Aurora, Ontario L4G 4C4 Canada
Phone: (800) 661-2461, Fax: (800) 390-3904
email: sales@hellermanntyton.ca

HellermannTyton Mexico

Anillo Periferico Sur 7980 Edificio 6A, Parque Industrial Tecnologico II
Santa María Tequepexpan, Tlaquepaque, Jalisco, Mexico 45601
Phone: 011-52-33-3-133-9880, Fax: 011-52-33-3-133-9861
email: info-mx@hellermanntyton.com

ISO 9001 certified

Warranty Policy

HellermannTyton products are warranted to be free from defects in material and workmanship at the time sold by us; but our obligation under this warranty and that of the seller is limited to the replacement of the product, and neither we nor the seller are bound by any other warranty, expressed, implied or statutory. Under no circumstances are we or the seller liable for any loss, damage, expenses or consequential damages of any kind arising out of the use or inability to use these products. All are sold with the understanding that the user will test them in actual use and determine their adaptability for the intended uses.