


Adhesive Mounting Bases

Cable Tie Mounting Bases - Rubber Adhesive

HellermannTyton Adhesive Cable Tie Mounting Bases are used with T18 through T150 Series cable ties to provide stability when securing bundles. The mounts are installed using the adhesive backing and/or by securing two or four screws. The 4-way opening allows the cable ties to be inserted parallel or perpendicular to the wire bundles. Rubber-based adhesive allows for a permanent bond to most surfaces.

Features and Benefits

- Durable adhesive achieves high pull-off force and is unaffected by vibration.
- 4-way opening allows cable ties to be installed parallel or perpendicular to bundles.
- Predrilled holes extend mounting options and security.
- Extended adhesive liner is easy to remove quickly.

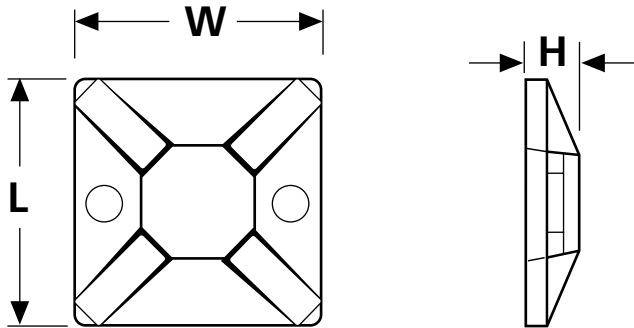

PART NO.	TYPE	Cable Tie Series	Length (L) in. (mm)	Width (W) in. (mm)	Height (H) in. (mm)	Material	Color	Pkg. Qty.
MB2.5A0C2	MB2.5A	T18	0.6 (15.9)	0.6 (15.9)	0.2 (4.1)	PA66	Black	100
MB2.5A10C2		T18	0.6 (15.9)	0.6 (15.9)	0.2 (4.1)	PA66	White	100
MB2.5A0M4		T18	0.6 (15.9)	0.6 (15.9)	0.2 (4.1)	PA66	Black	1000
MB2.5A10M4		T18	0.6 (15.9)	0.6 (15.9)	0.2 (4.1)	PA66	White	1000
MB3A0C2	MB3A	T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.6)	PA66	Black	100
MB3A10C2		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.6)	PA66	White	100
MB3A0M4		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.6)	PA66	Black	1000
MB3A10M4		T18 - T30	0.8 (19.0)	0.8 (19.0)	0.2 (4.6)	PA66	White	1000
MB4A0C2	MB4A	T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66	Black	100
MB4A10C2		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66	White	100
MB4A0H4		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66	Black	500
MB4A10H4		T18 - T50	1.1 (28.5)	1.1 (28.5)	0.2 (5.6)	PA66	White	500

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

*This product meets UL standards. Please see appendix for specific file numbers.

Bundling and Securing

Cable Tie Mounts

Adhesive Mounting Bases

Cable Tie Mounting Bases - Rubber Adhesive

PART NO.	TYPE	Cable Tie Series	Length (L) in. (mm)	Width (W) in. (mm)	Height (H) in. (mm)	Material	Color	Pkg. Qty.
MB4SHA0C2	MB4SHA	T18 - T50	1.1 (28.3)	1.1 (28.3)	0.2 (5.8)	PA66	Black	100
MB4SHA0H4		T18 - T50	1.1 (28.3)	1.1 (28.3)	0.2 (5.8)	PA66	Black	500
MB4SHA10H4		T18 - T50	1.1 (28.3)	1.1 (28.3)	0.2 (5.8)	PA66	White	500
MB4SHA10C2		T18 - T50	1.1 (28.3)	1.1 (28.3)	0.2 (5.8)	PA66	White	100
MB5A0C2	MB5A	T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	Black	100
MB5A10C2		T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	White	100
MB5A0F4		T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	Black	250
MB5A10F4		T18 - T150	1.5 (37.7)	1.5 (37.7)	0.3 (7.1)	PA66	White	250

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

*This product meets UL standards. Please see appendix for specific file numbers.