

Bundling and Securing

Self-Affixing Clips

Solar I-Beam Clips

Effectively routes PV cables


The Solar I-Beam Clip is a cable routing device affixed to the top cross section of an I-beam pile to reduce potential abrasion damage to PV cabling during cable pull operations. The oversized edge clip design can be top loaded or rolled into position, making it easier to attach to the post even after panels have been installed and space is restricted. This top-of-beam clip accommodates a wide range of I-beam thicknesses from 0.125" to 0.50". The I-Beam Clip is easy to install, creates less wobble, holds more wires and has better side loading resistance.



Features and Benefits

- Wide-body design prevents wobble caused by the lateral strain created during wire pull activities.
- Tool-free installation saves time and reduces installation costs.
- Clip-on styling for easy installation, even in constrained spaces.
- Cradle arms guide cabling and prevent bundles from escaping during pulling operations.
- Cable tie saddle for cinching down bundles when install is complete.

MATERIAL	Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)
Operating Temperature	-40°F to +230°F (-40°C to +110°C)
Color	Black (BK)

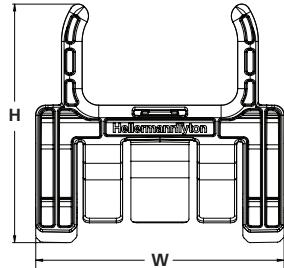

PART NO.	TYPE	Max. Bundle Diameter in. (mm)	I-Beam Thickness in. (mm)	Height (H) in. (mm)	Width (W) in. (mm)	Color	Pkg. Qty.
151-04320	IBBCLPSLR1	2.0 (50.8)	0.125 - 0.5 (3.3 - 12.7)	4.53 (115.0)	4.7 (119.8)	Black	500

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

HellermannTyton North American Corporate Headquarters
7930 N. Faulkner Rd, PO Box 245017
Milwaukee, WI 53224-9517
Phone: (414) 355-1130, (800) 537-1512
Fax: (414) 355-7341, (800) 848-9866
email: corp@htamericas.com
www.hellermann.tyton.com

IATF 16949, AS9100, ISO 9001 and ISO14001 certified

Warranty Policy – HellermannTyton products are warranted to be free from defects in material and workmanship at the time sold by us; but our obligation under this warranty and that of the seller is limited to the replacement of the product, and neither we nor the seller are bound by any other warranty, expressed, implied or statutory. Under no circumstances are we or the seller liable for any loss, damage, expenses or consequential damages of any kind arising out of the use or inability to use these products. All are sold with the understanding that the user will test them in actual use and determine their adaptability for the intended uses.

© HellermannTyton Corporation

HellermannTyton Canada
Unit #4, 205 Industrial Parkway North
Aurora, Ontario L4G 4C4 Canada
Phone: (800) 661-2461
Fax: (800) 390-3904
email: sales@hellermanntyton.ca

HellermannTyton Mexico
Anillo Periferico Sur 7980 Edificio 6A
Parque Industrial Tecnologico II
Santa Maria Tequepexpan
Tlaquepaque, Jalisco, Mexico 45601
Phone: 011-52-33-3-133-9880
Fax: 011-52-33-3-133-9861
email: info-mx@hellermanntyton.com
ISO 9001 certified

LITPD426, 07.2024