


TabTags™

# Easier to peel, faster installations

MADE FOR REAL®

## TabTags Instructions:

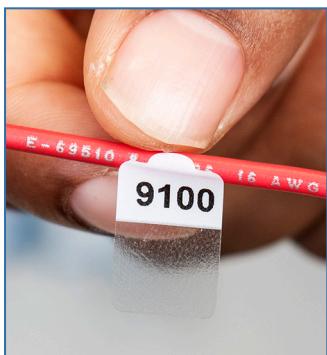

1. To peel off label, bend liner to expose tab.
2. Press just the tab onto the wire and align label as needed.
3. Wrap label and clear tail around wire to laminate the printed portion.
4. Finished application.

# Identification

## Labels

### Thermal Transfer Labels

#### TabTag™ Self-Laminating Labels


HellermannTyton TabTag thermal transfer self-laminating labels are a conformable vinyl film with a white printable surface followed by a clear tail that laminates the printed text when applied to a wire or cable. Handling the label by the tab helps keep fingers off the clear overlay, ensuring years of performance. The labels are UL recognized for indoor use with an aggressive acrylic adhesive that enables the label to bond to large and small diameter wires.

#### Features and Benefits

- Convenient tab is easier to remove from the liner, speeding labeling operations.
- Tab acts as a guide during positioning or repositioning to ensure a straight wrap and a high-quality appearance.
- Tab helps prevent label slippage when applied to cable insulation, reducing labor.
- In tests, TabTags increased the average number of wraps per hour by 12 percent, saving time and increasing output.



<b>MATERIAL</b>	Type 100B, Vinyl, white transparent, self-laminating (100B)
<b>Color</b>	White (WH)

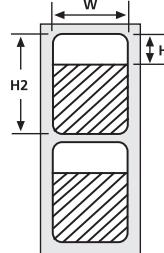

PART NO.	TYPE	Label Width (W) in. (mm)	Printable Area Height (H) in. (mm)	Label Height (H2) in. (mm)	Vertical Repeat in. (mm)	Horizontal Repeat in. (mm)	Liner Width in. (mm)	Color	Labels per Row	Pkg. Qty.
596-12200*	TAG2T5ES	0.50 (12.7)	0.50 (12.7)	1.56 (39.60)	1.74 (44.19)	0.66 (16.76)	3.35 (85.09)	White	5	10000
596-12201*	TAG22T3ES	1.00 (25.4)	0.50 (12.7)	1.56 (39.60)	1.74 (44.19)	1.07 (27.17)	3.35 (85.09)	White	3	5000
596-12202*	TAG51T3ES	1.00 (25.4)	0.37 (9.4)	0.82 (17.00)	1.0 (25.40)	1.07 (27.17)	3.35 (85.09)	White	3	10000
596-12203*	TAG26T6ES	0.50 (12.7)	0.37 (9.4)	0.82 (17.00)	1.0 (25.40)	0.62 (15.74)	4.00 (101.60)	White	6	10000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.



\* Please note - not all products listed on this page may have this approval. Please see [www.Hellermann.Tyton.com](http://www.Hellermann.Tyton.com) for the latest approvals.

#### HellermannTyton North American Corporate Headquarters

7930 N. Faulkner Rd, PO Box 245017  
Milwaukee, WI 53224-9517  
Phone: (414) 355-1130, (800) 537-1512  
Fax: (414) 355-7341, (800) 848-9866  
email: [corp@htamericas.com](mailto:corp@htamericas.com)  
[www.hellermann.tyton.com](http://www.hellermann.tyton.com)

**IATF 16949, AS9100, ISO 9001 and ISO14001 certified**

#### HellermannTyton Canada

Unit #4, 205 Industrial Parkway North  
Aurora, Ontario L4G 4C4 Canada  
Phone: (800) 661-2461  
Fax: (800) 390-3904  
email: [sales@hellermanntyton.ca](mailto:sales@hellermanntyton.ca)

#### HellermannTyton Mexico

Anillo Periferico Sur 7980 Edificio 6A  
Parque Industrial Tecnologico II  
Santa Maria Tequepexpan  
Tlaquepaque, Jalisco, Mexico 45601  
Phone: 011-52-33-3-133-9880  
Fax: 011-52-33-3-133-9861  
email: [info-mx@hellermanntyton.com](mailto:info-mx@hellermanntyton.com)

**ISO 9001 certified**

**Warranty Policy** – HellermannTyton products are warranted to be free from defects in material and workmanship at the time sold by us; but our obligation under this warranty and that of the seller is limited to the replacement of the product, and neither we nor the seller are bound by any other warranty, expressed, implied or statutory. Under no circumstances are we or the seller liable for any loss, damage, expenses or consequential damages of any kind arising out of the use or inability to use these products. All are sold with the understanding that the user will test them in actual use and determine their adaptability for the intended uses.